

Quick Reference Guide

Emergency Preparedness for Healthcare

RE-BOX® Industrial Enclosure

Industrial RE-BOX® Cabinet Configured for Cooling

Mount	Rack Units	Height	Width	Depth	Max Switch Depth	Catalog No.
Vertical	9U	36" (914mm)	24" (610mm)	16" (406mm)	16" (406)	IR3216APG
Horizontal	12U	24" (610mm)	24" (610mm)	24" (610mm)	20" (508)	IR222APG

Air Conditioning Unit for Industrial RE-BOX®

BTU	Height	Width	Depth	Weight	Amp Draw	Catalog No.
3000	21" (533mm)	12" (305mm)	10" (254mm)	54 lb	6	IRAC3
Cover plate for IRAC3						IRPG3

Equipment Shelf

Description	Dimensions	Catalog No.
Solid	2U x 19"W x 14"D	MCCCS19

Floor Mount Kits

Use With	Catalog No.
IR321APG	IRF1812
IR222APG	IRF1224

Cement Anchoring Kit

Description	Catalog No.
4-pack, 3.75" length, 3/8" diameter OD	HPWRR



Power and Connectivity

NEXTSPEED® Ascent Patch Panels, 19"

Category	24-Port	48-Port
6A	HPJ6A24*	HPJ6A48*
6	HP624	HP648

*Kit: includes 24 black HJU6ABK Cat 6A jacks

NEXTSPEED® Ascent Jacks

Category	Catalog No.
6A, COBRA-LOCK Termination	HJU6ABK
6	HXJ6BK

Black; additional colors and 24-packs available

NEXTSPEED® Category 6A Patch Cords

Length	Black	Blue
3ft	HC6ABK03	HC6AB03
10ft	HC6ABK10	HC6AB10

Additional colors, lengths and 24-packs available

Power Strip, Horizontal

Description	Catalog No.
15A-120V, NEMA 5-15R	HPWPWR


Field Termination Plug

Category	Catalog No.
6A	SP6A
6	SP6

NEXTSPEED® Category 6 Patch Cords

Length	Black	Blue
3ft	HC6BK03	HC6B03
10ft	HC6BK10	HC6B10

Additional colors, lengths and 24-packs available

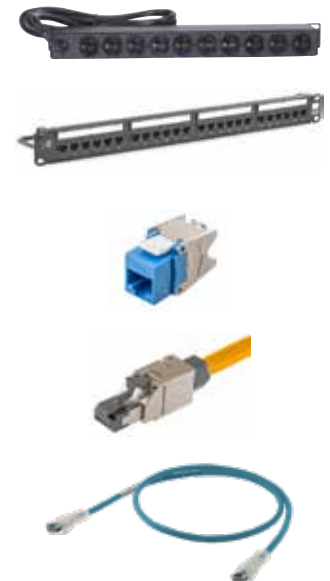

Quick Reference Guide

Emergency Preparedness for Healthcare

Copper Cable

NEXTSPEED® OSP Outdoor Cable


Category	Color	NVP	Spool
6A	Black	67%	C6ASOPBK
6	Black	63%	C6SOPBK

NEXTSPEED® Ascent UTP Standard Cable

Category	Color	NVP	Plenum Spool	Riser Spool
6A	Blue	Plenum 71%, Riser 68%	C6ASPB	C6ASRB
6A	Yellow	Plenum 71%, Riser 68%	C6ASPY	C6ASRY
			Plenum REELEX® Box	Riser REELEX® Box
6	Blue	Plenum 70%, Riser 68%	C6RPB	C6RRB
6	Yellow	Plenum 70%, Riser 68%	C6RPY	C6RRY

NEXTSPEED® Ascent FTP Shielded Cable

Category	Color	NVP	Plenum Spool	Riser Spool
6A	Blue	Plenum 70%, Riser 68%	C6AFTSPB	C6AFTSRB
6A	Yellow	Plenum 70%, Riser 68%	C6AFTSPY	C6AFTSRY

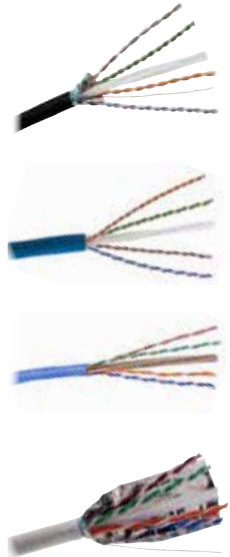

Wallplates and Frames

Wallplates with Label Fields

Ports	Stainless Steel	Office White
1	SSFL11	IFP11OW
2	SSFL12	IFP12OW
3	SSFL13	IFP13OW
4	SSFL14	IFP14OW
6	SSFL16	IFP16OW

Stainless Steel Phone Wallplates

Description	Flush Jack	Recessed Jack
USOC jack, RJ25, 6-position	SPUF	SPUR
Cat 5e jack, RJ45, 8-position	SP5EF	SP5ER
Cat 6 jack, RJ45, 8-position	SP6F	SP6R
10 Gig jack, RJ45, 8-position	SP10GF	SP10GR
Blank plate	P630S1G	

Decorator Keystone Frames

Ports	White	Blank Adapter
1	NS611W	NS620W
2	NS612W	
3	NS613W	
4	NS614W	
6	NS616W	

Surface Mount Boxes

Ports	Office White
1	HSB1OW
2	HSB2OW
4	HSB4OW
6	HSB6OW
12	HSB12OW

Additional colors available



Quick Reference Guide

Emergency Preparedness for Healthcare

Fiber Optic

FCR Enclosures

Units	Catalog No.
1U	FCR1U3SP
2U	FCR2U6SP

Pre-Polished LC Connectors

	12-Pack
OM3	FCLC900K50GM12
OS2	FCLC900KSM12



FSP Adapter Panels

Strands	OM3 LC MM	OS2 LC SM
6	FSPLCDM3AQ	FSPLCDS3B
12	FSPLCDM6AQ	FSPLCDS6B
24	FSPLCDM12AQ	FSPLCDS12B



Indoor/Outdoor Loose Tube Fiber Cable

	Plenum		Riser	
	6-Strand	12-Strand	6-Strand	12-Strand
50µm OM4 Multimode	HFCH2006P4BK	HFCH2012P4BK	HFCH2006R4BK	HFCH2012R4BK
9µm OS2 Singlemode	HFCH2006PSBK	HFCH2012PSBK	HFCH2006RSBK	HFCH2012RSBK



HI-Impact

Consolidation Point Enclosures

Rating	Width Inches (mm)	Depth Inches (mm)	Height Inches (mm)	Catalog No.
NEMA Rated 4X	12" (305)	6" (152)	12" (305)	HICPSS
NEMA Rated 4/12	12" (305)	6" (152)	12" (305)	HICP412G



HI-Impact Copper Panel Mount Connectors

Description	Catalog No.
HI-Impact Category 6 connector (UTP)	HI6
HI-Impact in-line coupler, Category 6	HI6C
Protective cap	HIC



HI-Impact Patch Cords

Description	3 feet	7 feet	10 feet
HI-Impact Cat 6 RJ45 to standard RJ45	HI603AE	HI607AE	HI610AE
HI-Impact Cat 6 RJ45 on both ends	HI603EE	HI607EE	HI610EE
Standard Cat 6 RJ45 on both ends	HI603AA	HI607AA	HI610AA

Additional lengths available

