


THE POWER TO PERSEVERE

Legrand Temporary and Permanent Power Solutions for Crisis Healthcare

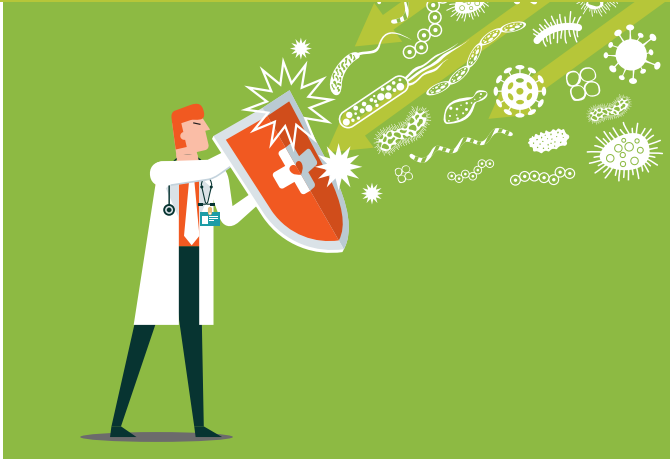

THE POWER TO KEEP YOU ON YOUR FEET.

In ever-changing situations, you need power solutions as nimble as you are. Luckily, when times get tough—we get even tougher. Legrand has a fully stocked line of temporary and permanent power solutions to solve your biggest healthcare challenges.

Perfect for:

- Building new wings and units to fulfill capacity requirements mandated by local governments
- Updating healthcare facilities to handle higher patient numbers and power up increasing quantities of vital equipment
- Temporary healthcare setups in buildings not originally designed for healthcare, like gymnasiums, convention centers and more

THE POWER THAT'S AS DEPENDABLE AS YOU.

No one can be slowed down by old or unreliable power supplies. Every piece of equipment has to be up and running, all of the time, without interruption. With over 125 years of experience in manufacturing electrical devices, you can rest assured that we've thought of everything. Installation is quick and efficient. Devices are code compliant, safe and rigorously tested. For end users, it's intuitive to plug in and get the connections they need to keep people safe. Whether you need to step in and replace old devices, or step up and help increase capacity, our options are in stock and ready to go.

• Hospital Grade PlugTail® Receptacles and Switches for lobbies, patient rooms and critical care units

- Installs 5x faster than conventional devices
- Get in and out of the project quickly
- Easily make upgrades or changes later
- Meet rigid test requirements for abrupt removal, ground contact overstress, impact resistance and assembly integrity

• Watertight and Antimicrobial Plugs and Connectors for anywhere you need power that's safe from moisture

- The toughest devices for heavy duty applications
- Keeps connections safe
- Tested to undergo varying levels of splashing and submersion

• Power Poles for hospital beds, nursing stations and more

- Quick installation
- Simple to use
- Designed to blend in and stay out of the way
- Combination of lighting and power

• Plugmold® Multioutlet Systems to bring necessary connections to tight locations

- Compact, low-profile design
- Easy installation

• Wiremold® Prewired Raceway

- Installs in 1/3 of the time and is ready for termination at the job site
- Wired and preassembled for fast, painless installation
- Quickly and easily delivers power to labs and other critical healthcare support stations

THE POWER TO PERSEVERE

Legrand Temporary and Permanent Power Solutions for Crisis Healthcare



THE POWER TO HELP TRANSFORM.

When put to the test, we know you outperform by making what you need at the job. You need temporary power that's just as inspired as you are. Don't wrangle with makeshift power setups and risk losing precious connections. Stock up on our portable options when you need to quickly bring power to atypical applications. They're easy to maneuver and simple to set up. Even better, they're code compliant and designed specifically for construction sites, new power setups and temporary situations.

• Hospital Grade Plug-In Outlet Centers for labs and other workstations

- Bring power safely and conveniently in a portable plug-in unit
- Low, space-saving profile that's aesthetically pleasing
- Includes lighted switch and resettable circuit breaker

• Portable GFCI Receptacles for on-the-go safety

- Adapt any receptacle to provide GFCI protection
- Auto-reset and water-resistant
- Watertight rubber cord grommets seal the GFCI from the environment

• Cam-Type Devices for continuous, worry-free power


- Enhanced durability and service life with increased insulation protection for safety
- Designed and engineered for interchangeability with other manufacturers' cam-type products
- UL Listed, CSA Certified and rated NEMA 3R and 4 for use in outdoor applications

• Turnlok® Locking Plugs and Connectors for when power can't be pulled

- NEMA configurations are always visible for fast ID without disconnecting
- Extra-rugged construction features chemical and impact-resistant nylon housings
- Industrial-strength, brass alloy plug blades and connector contacts and optional neoprene dust covers and weatherproof boots

• Cable Protectors for organization and reduced tripping hazards

- Multiple channels to safely manage onsite cables
- Convenient stake-down holes and handle for carrying
- Rugged, all-weather polyurethane construction stands up to heavy traffic
- Meets NEC and OSHA requirements

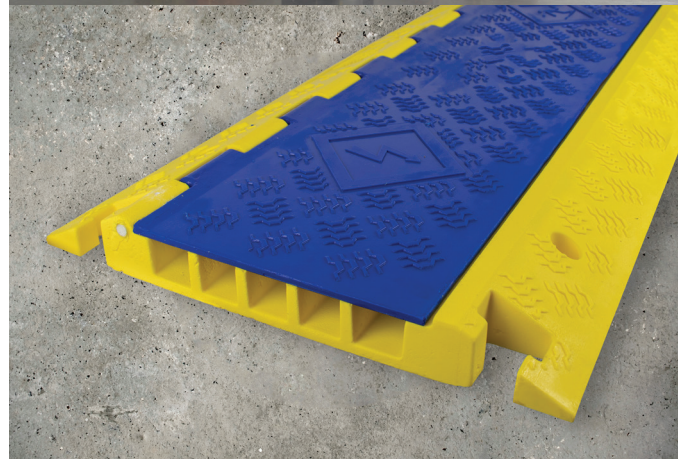

ITEM	DESCRIPTION
HOSPITAL GRADE GFCI	
2097HG*	SELF-TEST GFCI HOS GRD REC 20A 125V
2097HGTR*	SELF-TEST GFCI HOS GRD REC 20A 125V
2097HGTRWR*	SELF-TEST GFCI HOS GRD REC 20A 125V
PORTABLE GFCI	
2094PC2A	20A PORT GFCI 2 AUTO RESET
2094PC2M	20A PORT GFCI 2 MANUAL RESET
2094TL2A	20A PORT GFCI 2' TRNLK AUTO RESET
2094TL2M	20A PORT GFCI 2' TRNLK MANUAL RESET
PL204L	20A PORT GFCI BOX TRNLK AUTO RESET
PS204S	20A PORTABLE GFCI BOX AUTO RESET
HOSPITAL GRADE RECEPTACLES	
8300*	HOSP GRD DUP RECEPT 20A/125VAC
8300H*	COMPACT HG DUP REC 20A 125V
8301*	HOSP GRD SGL RECEPT 20A 125V
8801*	HOSP GRD SGL RECEPT 20A 250V
PS8300H*	HOSP GRAD HD DUP RECEPT 20A 125VAC
TR26362HGPI*	20A 125V DECO TR HG PWR IND
TR63H*	TR HOSP RECP 20A 125V
TR8300H*	TR COMPACT HG DUP REC 20A 125V
TR8300PI*	20A 125V IND GRD TR HG PWR IND
TR8301*	HG RECP SGL TR B&S WRE 20A/125V
HOSPITAL GRADE USB RECEPTACLES	
TR20USBAC*	20A 125V DUP TR REC + USBA USBC 3.1A
TR20USBAC6*	20A 125V TR REC + USBA+C FAST CHRGR
TR20HUSBAC*	20A 125V DUP HG TR REC+USBA USBC 3.1A
TR8300HUSB*	DUP REC 20A TR HG W/3.1A USB CHRGR
HOSPITAL GRADE PLUGTAIL RECEPTACLES	
PT26362HG*	PT DUP DECO HG 20A/125V
PT8300*	HOSP GRD EHD DUP RECEPT 20A/125V
PTIG8300*	PT HG ISO GROUND, 20 AMP
PTTR26362HG*	PT DUP DECO HG TR 20A/125V
PTTR5362HG*	PT DUP RECEPT HG TR 20A/125V
PTTR63H*	TAMPER RESISTANT HG EHD 20A/125V
PTTR8300*	PT DUP RECEPT HG TR 20A/125V
PTTR8300PI*	20A 125V PLUGTAIL TR HG PWR IND
COMMERCIAL SWITCHES	
CS20AC1*	20A 120/277VAC S WIRE COMM SP SW
CS20AC3*	20A 120/277VAC S WIRE COMM 3W SW
CSB20AC1*	20A 120/277VAC B+S WIRE COMM SP SW
CSB20AC3*	20A 120/277VAC B+S WIRE COMM 3W SW
2621*	SW DEC 1P 20A 120/277V GROUNDED
2623*	SW DEC 3W 20A 120/277V GROUNDED
PT2621*	PT SW DECO 20A 120/277V 1P
PT2623*	PT SW DECO 20A 120/277V 3P
PT20AC1*	PT 20A 120/277V SP SW
PT20AC3*	PT 20A 120/277V 3W SW

ITEM	DESCRIPTION
ANTIMICROBIAL PRODUCTS	
15W33AM	STR BL IP67 CONN 20A 125V 5-20R ANTI-MIC
15W47AM	STR BL IP67 CONN 15A 125V 5-15R ANTI-MIC
15W48AM	STR BL IP67 CONN 20A 250V 6-20R ANTI-MIC
15W49AM	STR BL IP67 CONN 15A 250V 6-15R ANTI-MIC
STAINLESS STEEL WALLPLATES	
SL1	PLATE SS430 1GANG TOGGLE W/OUT LINE
SL12	PLATE SS430 1G TELE W/OUT LINE
SL13	PLATE SS430 1GANG BLANK W/OUT LINE SS
SL14	PLATE SS430 1G BLANK W/OUT LINE SS
SL2	PLATE SS430 2G 2TOG W/OUT LINE
SL23	PLATE SS430 2GANG BLANK
SL24	PLATE SS430 2GANG BLANK W/OUT LINE
SL3	PLATE SS430 3G 3 TOG W/OUT LINE
SL4	PLATE SS430 4G 4 TOG W/OUT LINE
SL7	PLATE SS430 1G SGL RECP NO LINE
SL8	PLATE SS430 1GANG DUPLEX W/OUT LINE
SL82	PLATE SS430 2G 2 DUP W/OUT LINE
PLUGTAIL CONNECTORS	
PTRA6STR	90 DEGREE 6 IN PT CONNECTOR
PTRA6SOL	90 DEGREE 6 IN PT CNTR SOLID
PTRA6SOLB25	90 DEGREE 25 IN PT CNTR SOLID
PTRA6STRB25	90 DEGREE 25 IN PT CONNECTOR STRAND
PTRA6SOLBP	PT 90 DEG CONNECTOR SOLID WIRE WAGO
PTRA6STRBP	PT 90 DEG CONNECTOR STR WIRE WAGO
PTRA6STRB12	PT FEMALE CON 90 DEG STRAND WIRE 12
PTRA6SOLB12	PT FM CONN 90 DEG SOLID WIRE 12
PTRA6STRB180	90 DEGREE PT TAIL 15 FT LEAD
PTRA6STRB12NB	PT FEMALE CONN 90% STRAND WIRE 12
PTRA6STRXBB	PT #12 6IN XHHW BLACK/BLUE WIRE
PTRA6STRXBPG6	PT CONNECTOR 6IN XHHW STR PUSH IN 6G
PTRA6STRBPG6	PT CONNECTOR 6IN STR PUSH IN 6G 4H/N
PTRA6STRBPWG	PT 90 DEG CONNECTOR STR WIRE WAGO
PTS6STR3BPWG	PT SW CONN 6 IN STR 3 WIRE WAGO
PTS6STR4BPWG	PT SW CONN 6 IN STR 4 WIRE WAGO
CORD REELS	
CRCD123N50F20	20A, flying lead, 50' length, 12awg 3c
CRCD123N25R20	20A, quad rb, 25' length, 12awg, 3c
CRCD123N50R20	20A, quad RG, 50' length, 12awg, 3c
CRCD123G50R20	20A, GFCI, quad RB, 50' length, 12awg, 3c
WEATHERPROOF PRODUCTS	
WPB23*	WP BOX
WPRB25*	WP BOX ROUND
3726*	WP COVER
CA26G*	WP COVER
WIUC1*	WIUC COVER
WPG1*	WP COVER

*Base part numbers shown. More options in stock and available, contact your Legrand representative for more information.

ITEM	DESCRIPTION
PORTABLE POWER PLUG & CONNECTOR	
15W47	STR BLADE IP67 CONN 15A 125V 5-15R
14W47	STR BLADE IP67 PLUG 15A 125V 5-15P
PS5969Y	STR BLD CONN 3W 15A 125V Y
PS5965Y	STR BLD PLUG 3W 15A 125V Y
PS5269X	STR BLD CONN 3W 15A 125V B&W
PS5266X	STR BLD PLUG 3W 15A 125V B&W
PS5266XHG	STR BLD PLUG 3W 15A 125V HG
PS5269XHG	STR BLD CONN 3W 15A 125V HG
PS5266HGAN	STR BLD ANGLE PLUG 3W 15A 125V HG
PS5366XHG	STR BLD PLUG 3W 20A 125V HG
PS5466XHG	STR BLD PLUG 3W 20A 250V HG
PS5369XHG	STR BLD CONN 3W 20A 125V HG
PS5366HGAN	STR BLD ANGLE PLUG 3W 20A 125V HG
L630P	TURNLOK PLUG 3W 30A 250V B&W
L630C	TURNLOK CONNECTOR 3W 30A 250V
L620P	TURNLOK PLUG 3W 20A 250V B&W
L620C	TURNLOK CONNECTOR 3W 20A 250V
L530P	TURNLOK PLUG 3W 30A 125V B&W
L530C	TURNLOK CONNECTOR 3W 30A 125V
L520P	TURNLOK PLUG 3W 20A 125V B&W
L1430R	TURNLOK SGL RECEPT 4W 30A 125/250V
L1430P	TURNLOK PLUG 4W 30A 125/250V B&W
L1430C	TURNLOK CONNECTOR 4W 30A 125/250V
L1420P	TURNLOK PLUG 4W 20A 125/250V
L1420C	TURNLOK CONNECTOR 4W 20A 125/250V B&W
PS48062	75' HG EXT CABLE 5-15P TO 5-15R
PS48061	50' HG EXT CABLE 5-15P TO 5-15R
PS48072	8' HG EXT CABLE 5-15P TO 5-15R

ITEM	DESCRIPTION
HOSPITAL-GRADE PPOCS	
E10103	13" White w/ 3 5-15R Hospital Grade 15A, 6' Cord
E10118	13" White w/ 3 5-15R Hospital Grade 15A, 15' Cord
IVPM-100	IV Pole Mounting Kit
ULBH4-15	Plug-in-Outlet-Center Medical Grade, 120V/15A, 4 Outlets, 15' Cord
ULBH4-6	Plug-in-Outlet-Center Medical Grade, 120V/15A, 4 Outlets, 6' Cord
ULBH6-15	Plug-in-Outlet-Center Medical Grade, 120V/15A, 6 Outlets, 15' Cord
ULBH6-6	Plug-in-Outlet-Center Medical Grade, 120V/15A, 6 Outlets, 6' Cord
ULM4-15	Plug-in-Outlet Center Medical Grade, 120V/15A, 4 Outlets, 15' Cord
ULM4-6	Plug-in-Outlet Center Medical Grade, 120V/15A, 4 Outlets, 6' Cord
ULM6-15	Plug-in-Outlet Center Medical Grade, 120V/15A, 6 Outlets, 15' Cord
ULM6-20-15	Plug-in-Outlet Center Medical Grade, 120V/20A, 6 Outlets, 15' Cord
ULM620-6	Plug-in-Outlet Center Medical Grade, 120V/20A, 6 Outlets, 6' Cord
ULM6-6	Plug-in-Outlet Center Medical Grade, 120V/15A, 6 Outlets, 6' Cord
POLES	
30TP-212V	Two-Channel Power Pole, 12', Two 20A Duplex Receptacles
30TP-2V	Two-Channel Power Pole, 10', Two 20A Duplex Receptacles
30TP-412V	Two-Channel Power Pole, 12', Two 20A Duplex Receptacles
30TP-4V	Two-Channel Power Pole, 10', Two 20A Duplex Receptacles
25DTP	25 Series Pole, 10'
25DTP-12	25 Series Pole, 12'
304P0869	30TP-412V with Hospital Grade Receptacles and Switch
TEMPORARY POWER	
XCP5SLOT36	Cable Protector, 5-Channel, Standard
XCP3SLOT36	Cable Protector, 3-Channel, Heavy-Duty
RACEWAY	
V4000B-10	Steel Raceway Base 10' V4000 Ivory
G4000B-10	Steel Raceway Base 10' G4000 Gray
G4000C	Steel Raceway Cover 4000 Gray
V4000C	Steel Raceway Cover 4000 Ivory
G4000D	Steel Divider 4000
G4010B	Steel Raceway Blank End Fitting 4000 Gray
V4010B	Steel Raceway Blank End Fitting 4000 Ivory
V4017	Steel Raceway Interior Elbow 4000 Ivory
G4017	Steel Raceway Interior Elbow 4000 Gray
V4047RR	V4000 2-Gang Box with Two Rectangular Openings
G4047RR	G4000 2-Gang Box with Two Rectangular Openings
V4047-2RRRR	V4000 4-Gang Box with Four Receptacles
G4047-2RRRR	G4000 4-Gang Box with Four Receptacles
*Raceway also available in aluminum	